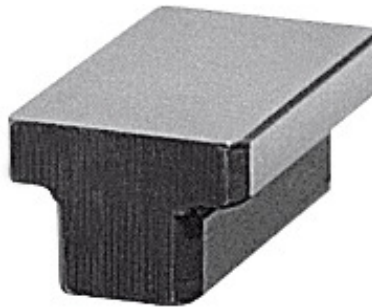


**Loose tenon ground for adjustment, Slot size b1 of the machine: 12/20mm****Order data**

Order number	375375 12/20
GTIN	4020772071837
Item class	35A

Description**Version:**

Precision ground all round, resulting in quick alignment times for appliances, vices etc., which are to be aligned parallel to the table slots of machine tools. A dial indicator is thus no longer required.

Application:

These loose tenons are inserted sideways into the slots after rough alignment of the fixture.

When transporting the fixture, there are then no tenons protruding underneath and the table cannot be damaged. 2 pieces are sufficient per machine, or 4 pieces for a double set-up.

Standard:

DIN 6323

Material:

Steel C 15, case-hardened.

Technical description

Height H ₁	5.5 mm
Slot size b ₂ of the jig	20 mm
Slot size b ₁ of the machine	12 mm
Length	32 mm

Height H	14 mm
Type	6323
Type of product	Tee-nut