


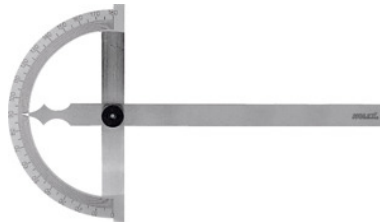

Protractor with open graduated arc, Graduated arc Ø×Stock length: 150X200 mm



Order data

Order number	453000 150X200
GTIN	4045197205902
Item class	42F

Description

Version:

Open semicircular graduated arc with graduation 0 – 180°; reading 1°.

Non-glare matt chrome-plated scale. With clamping nut.

Calibration: F3

Scale divisions: 1 degrees

Error limit: ±30 arcmin

Technical description

Graduated arc Ø	150 mm
Stock length	200 mm
Scale divisions	1 degrees
Error limit	±30 arcmin
Standard	Manufacturer's standard
Measurement technology	analogue
Material	Stainless steel, INOX
all parts	hardened
Packaging	Wallet

Calibration	F3
Type of product	Protractor

Services

Calibration Protractor	015360
Labelling laser-etched Type	018940
Calibration Protractor Type GRAD	025810 GRAD
GRAD	025820 GRAD