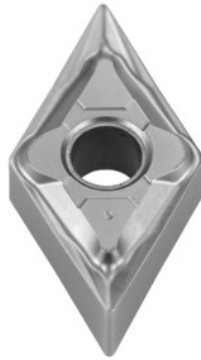


**Garant****DN.G 150604, Grade: HU7305**

## Order data

Order number	250760 HU7305
GTIN	4045197828590
Item class	21G

## Description

DN.G 150604 HU7305 Grade: HU7305  
Chip breaker: AM  
Tolerance: G  
Cutting depth  $a_p$ : 0.5 - 5 mm  
Feed  $f$ : 0.1 - 0.6 mm/rev.  
Cutting speed  $v_c$  main application: 400 - 600 m/min

## Technical description

Grade	HU7305
Cutting depth $a_p$	0.5 - 5 mm
Main application	N
Feed $f$	0.1 - 0.6 mm/rev.
Cutting conditions	slightly interrupted
Cutting speed $v_c$ main application	400 - 600 m/min
Corner radius	0.4 mm

Chip breaker	AM
Finishing/roughing assignment	Skrubbearbejdning-sletbearbejdning
Tool material	Carbide
Coating	uncoated
ISO code indexable insert	DNMG 150604
Number of changes/inserts	4
Tolerance	G
Type of product	Indexable insert for turning