


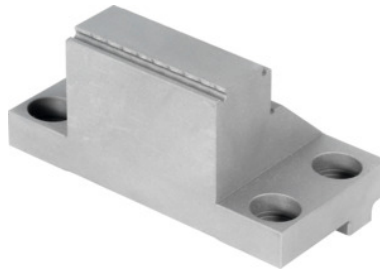

Gripp jaw, for T-REX fixed, for type: 64



Order data

Order number	361217 64
GTIN	4250364402316
Item class	34A

Description

Version:

Rigid anti-vibration design for parts clamped upright. Additional clamping area, ground both sides.

Application:

For rectangular workpieces (saw-cut blanks) // ≤ 0.5 mm

Suitable for:

Fixed jaws for T-Rex No. 361202.

Technical description

Step s	4 mm
Jaw length l	62.5 mm
c ₁	22 mm
b ₁	64 mm
Height h ₃	14 mm
Jaw height h	55 mm
Height h ₂	35 mm
c	12 mm

for type	64
Height h_1	52 mm
suitable for colour code	T-Rex
Jaw width b	96 mm
Type of product	Vice jaws