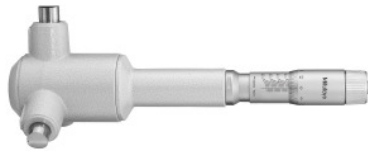


**Mitutoyo**
**Internal micrometer Holtest, Measuring range: 150-175mm**

**Order data**

Order number	429000 150-175
GTIN	4946368517797
Item class	44A

**Description**
**Version:**

Stainless, all reading parts glare-free satin chrome-plated. Barrel with jet black scale and ratchet. For through holes, measuring faces of hardened steel.

**Optional extras:**

Extensions No. 429010. Setting rings No. 484030.

**Technical description**

Dimension a	19.6 mm
Overall length	249 mm
Barrel Ø	23 mm
Standard measuring depth	147 mm
Measuring depth with extension	297 mm
Measuring range	150 - 175 mm
Error limit	0.01 mm
Scale divisions	0.005 mm
Standard	Manufacturer's standard
Micrometer barrel graduations	1/50 mm
Measurement technology	analogue

Packaging	sturdy box
Calibration	B6
Type of product	3-point internal micrometer

## Services

DAkkS calibration 3-point internal micrometer maximum measuring range 200 mm	022510 200
Calibration 3-point internal micrometer maximum measuring range 200 mm	022500 200

## Accessories

Setting ring DIN 2250 C Nominal size $\varnothing$ 160 mm	484030 160
Extension for internal micrometer Type 4/150	429010 4/150
Setting ring DIN 2250 C Nominal size $\varnothing$ 175 mm	484030 175