


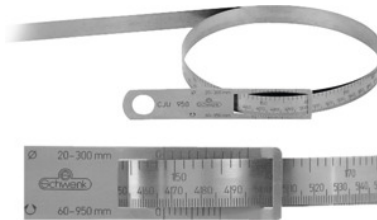

Stainless steel measuring tape for circumference and \emptyset , maximum total measuring range: 2200mm



Order data

Order number	465682 2200
GTIN	2050001060587
Item class	46R

Description

Version:

Steel measuring tape **CJU** for measuring external circumferences and \emptyset of spherical bodies. The spring steel strip is laser scaled on the front with 2 scales, one for circumference and the other for \emptyset . Graduations 1 mm. **Vernier reading 0.1 mm**. Scale graduation error limits to DIN 866.

V2A version made of stainless spring steel.

Note:

Measuring tapes C with reading 0.05 mm and measuring tapes with black coating available on request. Fixed version CJU on request.

Technical description

Tape width	16 mm
Measuring range for circumferences	940 - 2200 mm
Measuring range for \emptyset	300 - 700 mm
Scale divisions	0.1 mm
Tape thickness	0.2 mm
Calibration	G2
Type of product	Measuring tape

Services

Calibration
Circumference tape measure maximum length
3000 mm

026280 3000