


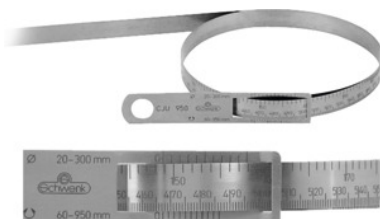

Stainless steel measuring tape for circumference and \emptyset , maximum total measuring range: 3460mm



Order data

Order number	465682 3460
GTIN	2050001060594
Item class	46R

Description

Version:

Steel measuring tape **CJU** for measuring external circumferences and \emptyset of spherical bodies. The spring steel strip is laser scaled on the front with 2 scales, one for circumference and the other for \emptyset . Graduations 1 mm. **Vernier reading 0.1 mm**. Scale graduation error limits to DIN 866.

V2A version made of stainless spring steel.

Note:

Measuring tapes C with reading 0.05 mm and measuring tapes with black coating available on request. Fixed version CJU on request.

Technical description

Measuring range for circumferences	2190 - 3460 mm
Measuring range for \emptyset	700 - 1100 mm
Tape width	16 mm
Scale divisions	0.1 mm
Tape thickness	0.2 mm
Calibration	G2
Type of product	Measuring tape

Services

Calibration
Circumference tape measure maximum length
6000 mm

026280 6000