


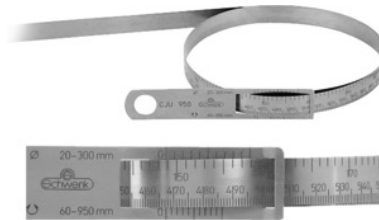

## Stainless steel measuring tape for circumference and $\emptyset$ , maximum total measuring range: 4720mm



### Order data

Order number	465682 4720
GTIN	2050001060600
Item class	46R

### Description

#### Version:

Steel measuring tape **CJU** for measuring external circumferences and  $\emptyset$  of spherical bodies. The spring steel strip is laser scaled on the front with 2 scales, one for circumference and the other for  $\emptyset$ . Graduations 1 mm. **Vernier reading 0.1 mm**. Scale graduation error limits to DIN 866.

**V2A version** made of stainless spring steel.

#### Note:

Measuring tapes C with reading 0.05 mm and measuring tapes with black coating available on request. Fixed version CJU on request.

### Technical description

Tape width	16 mm
Measuring range for circumferences	3450 - 4720 mm
Measuring range for $\emptyset$	1100 - 1500 mm
Scale divisions	0.1 mm
Tape thickness	0.2 mm
Calibration	G2
Type of product	Measuring tape

---

## Services

Calibration  
Circumference tape measure maximum length  
6000 mm

026280 6000