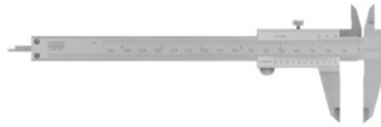


**Vernier caliper for left-handed use, Measuring range: 150mm****Order data**

Order number	410405 150
GTIN	4045197217677
Item class	41Z

Description**Version:**

Satin chromium plated anti-glare reading parts.

Locking screw at the top.

Fine, high-contrast scale.

Precision lapped measuring faces.

For left-handers.**Supplied with:**

Including thread table No. 412180 for caliper back.

Technical description

Jaw length	40 mm
Measuring range	0 - 150 mm
Packaging	Wallet
Scale divisions	0.05 mm
Calibration	A1
Graduation	1/20 mm
Graduation	1/128 in
Reversible reading	mm / inch
Standard	ISO 13385
Depth gauge	rectangular 3.7×1.3

Depth gauge available	yes
Measurement deviation E MPE	± 0.05 mm
Locking	Locking screw at top
Measurement technology	analogue
Material	Stainless steel, INOX
all parts	hardened
Thread table	Calipers table
Type of product	Universal calipers

Services

CalibrationCalipers / depth gauges maximum measuring range 200 mm	021000 200
DAkkS calibrationCalipers / depth gauges maximum measuring range 200 mm	021010 200

Accessories

Synthetic leather case for vernier calipers	412500
---	--------