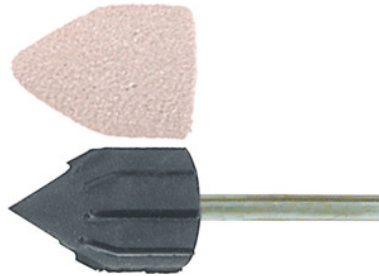


Garant**Abrasive cap holder, Head Ø, head length, shape: 1319G****Order data**

| | |
|--------------|---------------|
| Order number | 553100 1319G |
| GTIN | 4045197330499 |
| Item class | 51E |

Description**Version:**

The seamlessly formed abrasive caps slide on to the rubber body and are securely held in place by centrifugal force when the machine is running. **Abrasive caps can be replaced quickly and easily** (replace in direction of slots).

Slotted, resilient rubber body with steel shank.

Application:

Used mostly in tool making for finishing where access is difficult.

Suitable for :

Abrasive caps No. 553035 – 553328.

Shank Ø: 3 mm

maximum speed: 35000 min⁻¹

Technical description

| | |
|-----------------|-------------------------|
| Head Ø | 13 mm |
| maximum speed | 35000 min ⁻¹ |
| Shank Ø | 3 mm |
| Head length | 19 mm |
| Type of product | Abrasive cap holders |

