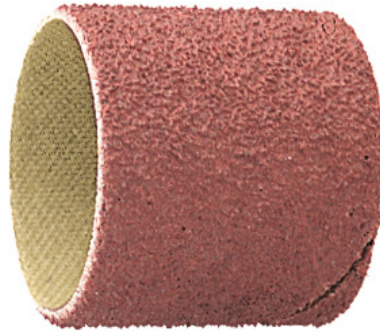


HOLEX**Abrasive sleeve (A) 60 grit medium coarse, Sleeve Ø×Width of sleeve:
15X30mm****Order data**

| | |
|--------------|---------------|
| Order number | 553710 15X30 |
| GTIN | 4045197240293 |
| Item class | 52E |

Description**Version:**

The rubber body of the abrasive sleeve holder expands at high speed to hold the abrasive sleeve in place. The full width of the sleeve can be used, it does not slip and can be replaced quickly and easily (twist in the direction of slots when fitting/removing). Only compatible with abrasive sleeve holders.

Made of non-tearing, synthetic resin bonded material with long service life and good grit adhesion. Unsuitable for use with cooling lubricants.

Aluminium oxide (A).

Application:

Abrasive sleeves are predominantly used for surface grinding tasks which require the removal of large amounts of material – even at sharp edges.

Suitable for:

Abrasive sleeve holder No. 553600.

Technical description

| | |
|--------------|-------|
| Grit | 60 |
| Sleeve width | 30 mm |

| | |
|----------------------|--------------------------|
| Sleeve Ø | 15 mm |
| Grit designation | medium coarse |
| Grinding media | Standard Aluminium Oxide |
| Grinding medium code | A |
| Sleeve shape | cylindrical |
| Type of product | Abrasive sleeve |

User data

| | Suitability | V _c | ISO code |
|--------------------------------|---|----------------|----------|
| Alu Mg | suitable | | |
| Steel < 900 N/mm ² | suitable | | |
| Steel < 1400 N/mm ² | suitable only under restricted conditions | | |
| Steel < 55 HRC | suitable only under restricted conditions | | |
| INOX | suitable only under restricted conditions | | |
| GG(G) | suitable only under restricted conditions | | |
| CuZn | suitable | | |
| Plastic, GRP | suitable | | |
| Wood | suitable | | |
| dry | suitable | | |

Accessories

Abrasive sleeve holder, slit, shank Ø 6 mm Head Ø×head length 15X30 mm

553600 15X30