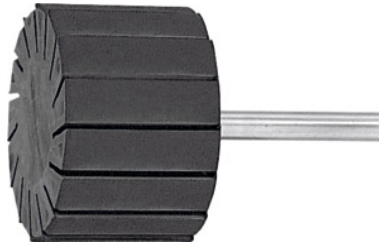


**Abrasive sleeve holder, slit, shank \varnothing 6 mm, Head \varnothing ×head length: 30X30mm****Order data**

Order number	553600 30X30
GTIN	4045197240200
Item class	52E

Description**Version:**

Slotted, resilient rubber body with steel shank. Ground outer face for best concentricity.

Technical description

minimum speed	13000 min ⁻¹
maximum speed	19100 min ⁻¹
Head \varnothing	30 mm
Head length	30 mm
Shape description	cylindrical
Shank \varnothing	6 mm
Backing material	resilient rubber body
Type of product	Tool sleeve carrier