


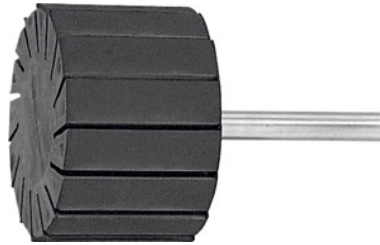

Abrasive sleeve holder, slit, shank \varnothing 6 mm, Head \varnothing ×head length: 45X30mm



Order data

Order number	553600 45X30
GTIN	4045197240217
Item class	52E

Description

Version:

Slotted, resilient rubber body with steel shank. Ground outer face for best concentricity.

Technical description

minimum speed	9000 min ⁻¹
maximum speed	12700 min ⁻¹
Head \varnothing	45 mm
Head length	30 mm
Shape description	cylindrical
Shank \varnothing	6 mm
Backing material	resilient rubber body
Type of product	Tool sleeve carrier