


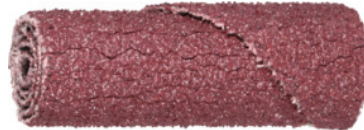

Abrasive roll, cylindrical (A) 80 grit medium, Abrasive roll Ø× abrasive roll length: 13X38mm



Order data

| | |
|--------------|---------------|
| Order number | 553880 13X38 |
| GTIN | 4045197524546 |
| Item class | 52E |

Description

Version:

Abrasive roll consisting of wound abrasive cloth with **Aluminium Oxide (A)**.
Cylindrical form.

Suitable for:

Abrasive roll holder No. 553835.

Suitable for:

Holder mounting Ø × overall length: 3×70

Technical description

| | |
|----------------------|--------------------------|
| Grit | 80 |
| Sander roller Ø | 13 mm |
| Sander roller length | 38 mm |
| maximum speed | 26000 min ⁻¹ |
| Grit designation | medium |
| Grinding media | Standard Aluminium Oxide |
| Grinding medium code | A |
| Sander roller form | cylindrical |
| Type of product | Abrasive roll |

User data

| | Suitability | V _c | ISO code |
|--------------------------------|---|----------------|----------|
| Alu Mg | suitable | | |
| Steel < 900 N/mm ² | suitable | | |
| Steel < 1400 N/mm ² | suitable | | |
| Steel < 55 HRC | suitable | | |
| Steel < 60 HRC | suitable only under restricted conditions | | |
| INOX | suitable only under restricted conditions | | |
| GG(G) | suitable only under restricted conditions | | |
| CuZn | suitable | | |
| Plastic, GRP | suitable | | |
| Wood | suitable only under restricted conditions | | |
| dry | suitable | | |

Accessories

Abrasive roll holder 6 mm shank Ø Mounting-Ø×Overall length 3X70 mm

553835 3X70