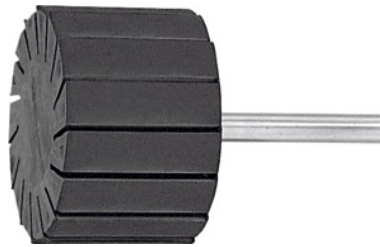


**Abrasive sleeve holder, slit, shank \varnothing 6 mm, Head \varnothing ×head length: 15X30mm****Order data**

Order number	553600 15X30
GTIN	4045197240170
Item class	52E

Description**Version:**

Slotted, resilient rubber body with steel shank. Ground outer face for best concentricity.

Technical description

maximum speed	36000 min ⁻¹
minimum speed	25000 min ⁻¹
Head \varnothing	15 mm
Head length	30 mm
Shape description	cylindrical
Shank \varnothing	6 mm
Backing material	resilient rubber body
Type of product	Tool sleeve carrier