


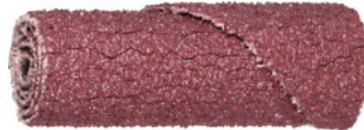

Abrasive roll, cylindrical (A) 80 grit medium, Abrasive roll Ø× abrasive roll length: 20X38mm



Order data

Order number	553880 20X38
GTIN	4045197524553
Item class	52E

Description

Version:

Abrasive roll consisting of wound abrasive cloth with **Aluminium Oxide (A)**.
Cylindrical form.

Suitable for:

Abrasive roll holder No. 553835.

Suitable for:

Holder mounting Ø × overall length: 5×85

Technical description

Grit	80
maximum speed	18000 min ⁻¹
Sander roller Ø	20 mm
Sander roller length	38 mm
Grit designation	medium
Grinding media	Standard Aluminium Oxide
Grinding medium code	A
Sander roller form	cylindrical
Type of product	Abrasive roll

User data

	Suitability	V _c	ISO code
Alu Mg	suitable		
Steel < 900 N/mm ²	suitable		
Steel < 1400 N/mm ²	suitable		
Steel < 55 HRC	suitable		
Steel < 60 HRC	suitable only under restricted conditions		
INOX	suitable only under restricted conditions		
GG(G)	suitable only under restricted conditions		
CuZn	suitable		
Plastic, GRP	suitable		
Wood	suitable only under restricted conditions		
dry	suitable		

Accessories

Abrasive roll holder 6 mm shank Ø Mounting-Ø×Overall length 5X85 mm

553835 5X85