


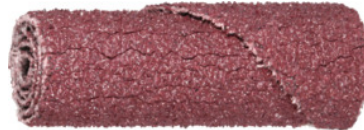

## Abrasive roll, cylindrical (A) 150 grit fine, Abrasive roll $\varnothing$ × abrasive roll length: 13X38mm



### Order data

Order number	553885 13X38
GTIN	4045197524591
Item class	52E

### Description

#### Version:

Abrasive roll consisting of wound abrasive cloth with **Aluminium Oxide (A)**.  
Cylindrical form.

#### Suitable for:

Abrasive roll holder No. 553835.

#### Suitable for:

Holder mounting  $\varnothing$  × overall length: 3×70

### Technical description

Sander roller length	38 mm
Grit	150
maximum speed	26000 min <sup>-1</sup>
Sander roller $\varnothing$	13 mm
Grit designation	fine
Grinding media	Standard Aluminium Oxide
Grinding medium code	A
Sander roller form	cylindrical
Type of product	Abrasive roll

## User data

	Suitability	V <sub>c</sub>	ISO code
Alu Mg	suitable		
Steel < 900 N/mm <sup>2</sup>	suitable		
Steel < 1400 N/mm <sup>2</sup>	suitable		
Steel < 55 HRC	suitable		
Steel < 60 HRC	suitable only under restricted conditions		
INOX	suitable only under restricted conditions		
GG(G)	suitable only under restricted conditions		
CuZn	suitable		
Plastic, GRP	suitable		
Wood	suitable only under restricted conditions		
dry	suitable		

## Accessories

Abrasive roll holder 6 mm shank Ø Mounting-Ø×Overall length 3X70 mm

553835 3X70