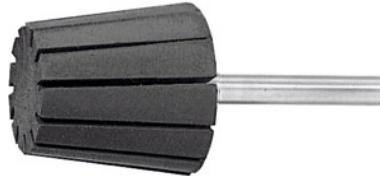


**Abrasive sleeve holder slit, conical shank 6 mm Ø, largest Ø×head length: 29X30mm****Order data**

Order number	553830 29X30
GTIN	4045197240569
Item class	52E

**Description****Version:**

Slotted, resilient rubber body with steel shank. Ground outer face for best concentricity.

**Technical description**

largest Ø	29 mm
smallest Ø	22 mm
maximum speed	21000 min <sup>-1</sup>
Head Ø	5 mm
Head length	30 mm
Shape description	conical
Shank Ø	6 mm
Backing material	resilient rubber body
Type of product	Tool sleeve carrier