


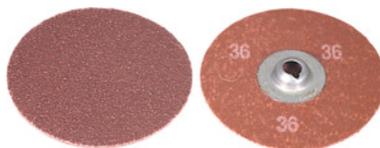

Grinding disc (A), Ø 76.2 mm, Grit: 80



Order data

| | |
|--------------|---------------|
| Order number | 553955 80 |
| GTIN | 4045197526298 |
| Item class | 52E |

Description

Version:

Optimum connection between the backing pad and grinding disc by the quick-clamping system (internal thread). Easy and quick disc replacement by hand, even after heavy use.

Standard Aluminium Oxide (A) for general-purpose use.

Sanding disc is centralised, resulting in vibration-free concentricity.

Application:

For efficient sanding down of small areas, even with varying contours in tool, mould and model making, machine, plant and container building. Reduced tool changing times save costs on multi-stage operations.

Note:

Other dimensions and grits available on request.

Technical description

| | |
|------------------------|-----------------------------|
| Grit | 80 |
| Disc Ø | 76.2 mm |
| Grinding media | Regular aluminium oxide (A) |
| Grinding medium code | A |
| Product name attribute | Ø 76.2 mm |
| maximum speed | 20000 min ⁻¹ |
| Type of product | Grinding wheel |

User data

| | Suitability | V _c | ISO code |
|--------------------------------|---|----------------|----------|
| Alu Mg | suitable | | |
| Steel < 900 N/mm ² | suitable | | |
| Steel < 1400 N/mm ² | suitable | | |
| Steel < 55 HRC | suitable only under restricted conditions | | |
| INOX | suitable only under restricted conditions | | |
| GG(G) | suitable only under restricted conditions | | |
| CuZn | suitable | | |
| Plastic, GRP | suitable | | |
| Wood | suitable | | |
| dry | suitable | | |

Accessories

Rubber backing pad shank Ø 6 mm medium hard External
Ø 75M mm

553920 75M