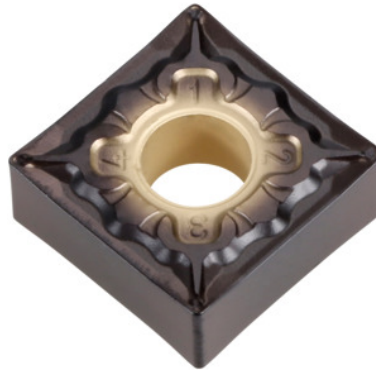


Garant
SNMG 120404, Grade: HB7035-1


Order data

Order number	251142 HB7035-1
GTIN	4045197874467
Item class	21G

Description

SNMG 120404 HB7035-1 Corner radius: 0.4 mm
 Grade: HB7035-1
 Chip breaker: SS
 Cutting depth a_p : 0.3 - 2 mm
 Feed f : 0.1 - 0.4 mm/rev.
 Cutting speed v_c main application: 120 - 350 m/min

Technical description

Corner radius	0.4 mm
Cutting depth a_p	0.3 - 2 mm
Feed f	0.1 - 0.4 mm/rev.
Chip breaker	SS
Main application	P
Cutting conditions	heavily interrupted
Cutting speed v_c main application	120 - 350 m/min

Grade	HB7035-1
Finishing/roughing assignment	Finishing
Tool material	Carbide
ISO code indexable insert	SNMG 120404
Number of changes/inserts	8
Type of product	Indexable insert for turning