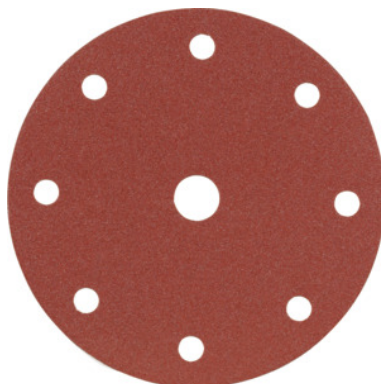


STARCKE®**Paper velour-backed abrasive disc (A) 8 + 1 holes, Ø 150 mm, Grit: 120****Order data**

Order number	567755 120
GTIN	4002748776748
Item class	56Z

Description**Version:**

Abrasive paper thickness 540 FK (F-paper, 40 to 180 grit) or thickness 544 C3K (240 – 800 grit, stearate coated) with **high strength and dense distribution**.

High material removal rates due to specially treated abrasive grit **(A)**.

The **back of the disc is covered with velour loops which automatically cling on** allowing quick disc change.

With 9-hole perforation for Festo RO 1E/RO 2E/WET 2E, Makita BO6030, Bosch GX 150 with dust extraction.

Application:

General purpose for grinding metal, non-ferrous metals, varnish, paint, wood, and plastic.

On **orbital sanders** with hook and loop pads e.g. No. 567885 / 567990. Maximum circumferential speed **40 m/s**.

Technical description

Grit	120
Disc Ø	150 mm
Grinding medium code	A

Iron, sulphur and chlorine constituents	< 0.1 %
Product name attribute	Ø 150 mm
Number of dust extraction holes	9
Propulsive equipment	Orbital sander
maximum circumferential speed	40 m/s
Type of product	Velour-backed abrasive disc

User data

	Suitability	V _c	ISO code
Alu Mg	suitable only under restricted conditions		
Steel < 900 N/mm ²	suitable		
Steel < 1400 N/mm ²	suitable		
Steel < 55 HRC	suitable		
Steel < 60 HRC	suitable		
Steel < 67 HRC	suitable only under restricted conditions		
INOX	suitable only under restricted conditions		
Ti	suitable only under restricted conditions		
CuZn	suitable		
Plastic, GRP	suitable		
Wood	suitable		
Paint	suitable only under restricted conditions		
Uni	suitable		
dry	suitable		

Accessories

PU hook and loop backing pad Multiple holes Outer Ø 150 mm	567887 150
Multi-hole PU backing pad External Ø 147 mm	567990 147
PU hook and loop backing pad External Ø 150 mm	567885 150