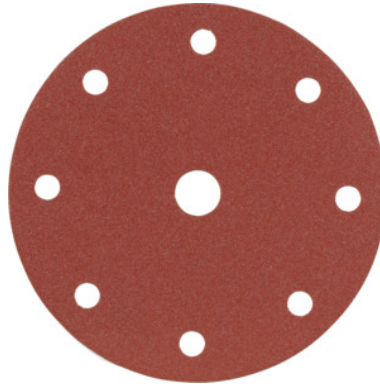


STARCKE®**Paper velour-backed abrasive disc (A) 8 + 1 holes, Ø 150 mm, Grit: 180****Order data**

| | |
|--------------|---------------|
| Order number | 567755 180 |
| GTIN | 4002748776960 |
| Item class | 56Z |

Description**Version:**

Abrasive paper thickness 540 FK (F-paper, 40 to 180 grit) or thickness 544 C3K (240 – 800 grit, stearate coated) with **high strength and dense distribution**.

High material removal rates due to specially treated abrasive grit **(A)**.

The **back of the disc is covered with velour loops which automatically cling on** allowing quick disc change.

With 9-hole perforation for Festo RO 1E/RO 2E/WET 2E, Makita BO6030, Bosch GX 150 with dust extraction.

Application:

General purpose for grinding metal, non-ferrous metals, varnish, paint, wood, and plastic.

On **orbital sanders** with hook and loop pads e.g. No. 567885 / 567990. Maximum circumferential speed **40 m/s**.

Technical description

| | |
|----------------------|--------|
| Grit | 180 |
| Disc Ø | 150 mm |
| Grinding medium code | A |

| | |
|---|-----------------------------|
| Iron, sulphur and chlorine constituents | < 0.1 % |
| Product name attribute | Ø 150 mm |
| Number of dust extraction holes | 9 |
| Propulsive equipment | Orbital sander |
| maximum circumferential speed | 40 m/s |
| Type of product | Velour-backed abrasive disc |

User data

| | Suitability | V _c | ISO code |
|--------------------------------|---|----------------|----------|
| Alu Mg | suitable only under restricted conditions | | |
| Steel < 900 N/mm ² | suitable | | |
| Steel < 1400 N/mm ² | suitable | | |
| Steel < 55 HRC | suitable | | |
| Steel < 60 HRC | suitable | | |
| Steel < 67 HRC | suitable only under restricted conditions | | |
| INOX | suitable only under restricted conditions | | |
| Ti | suitable only under restricted conditions | | |
| CuZn | suitable | | |
| Plastic, GRP | suitable | | |
| Wood | suitable | | |
| Paint | suitable only under restricted conditions | | |
| Uni | suitable | | |
| dry | suitable | | |

Accessories

| | |
|--|------------|
| PU hook and loop backing pad External Ø 150 mm | 567885 150 |
| Multi-hole PU backing pad External Ø 147 mm | 567990 147 |
| PU hook and loop backing pad Multiple holes Outer Ø 150 mm | 567887 150 |