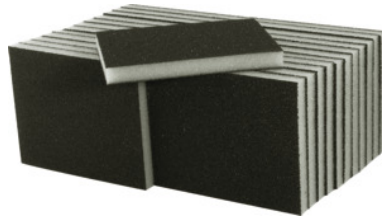


**3M****Abrasive sponge pack, 24 pieces extra soft, 125×98×13 mm, Grit: 100**

## Order data

Order number	557530 100
GTIN	4046719251773
Item class	53M

## Description

### Version:

**Abrasive sponge** with **extra-soft** intermediate layer. An outstanding fit to all profiles. **Coated on 2 sides.**

Silicon carbide (SiC)

### Advantage:

- **Resilient, no formation of kinks or folds.**
- **All sponges also suitable for wet grinding.**
- **Low tendency to clog, can be washed out.**

### Application:

For **finish smoothing of irregularities and profiled surfaces** without changing the geometry. Grinding metal, wood and plastics before painting, or between coats of paint, to provide a key.

Grinding medium code: SiC

Grit designation: fine

## Technical description

Grit	100
Grit designation	fine
Grinding media	Silicon carbide (SiC)
Grinding medium code	SiC
Width	98 mm

Height	13 mm
Length	125 mm
Product name attribute	125×98×13 mm
Number of coated surfaces	2
Number of sponges, pads	24
Type of product	Abrasive sanding sponge

### User data

	Suitability	V <sub>c</sub>	ISO code
Alu Mg	suitable		
Steel < 900 N/mm <sup>2</sup>	suitable		
Steel < 1400 N/mm <sup>2</sup>	suitable		
Steel < 55 HRC	suitable		
Steel < 60 HRC	suitable		
Steel < 67 HRC	suitable only under restricted conditions		
INOX	suitable		
Ti	suitable		
GG(G)	suitable		
CuZn	suitable		
Plastic, GRP	suitable		
Wood	suitable		
Stone	suitable only under restricted conditions		
Paint	suitable		
Uni	suitable		
wet maximum	suitable		
dry	suitable		

