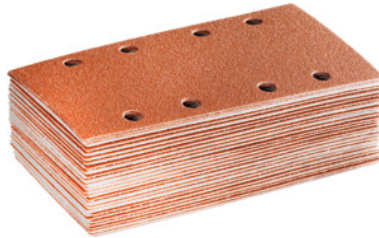


**STARCKE®****Abrasive paper pack, 50 pieces 8 holes, Grit: 80****Order data**

Order number	557576 80
GTIN	4002748356353
Item class	56Z

**Description****Version:**

Flexible B or C paper, containing latex, spread with Aluminium Oxide (542B7 / 542C7). **Back with hook and loop fastener** for quick change of sheets and high tear resistance.

**Advantage:**

For sanding wood and painted surfaces

- **Outstanding grit bonding – long service life, no premature grit break-away damage to surfaces.**
- **Dust-repellent additives prevent clogging with grinding dust.**
- **High-quality Aluminium Oxide grit for max. grinding performance right to the end.**

**Application:**

Grinding of primed paintwork, fillers, finish paintwork together with deburring and roughening of plastic components and general preparation of wood.

**Technical description**

Grit	80
Grit designation	coarse
Width	93 mm
Length	185 mm
Type of product	Hook-and-loop sandpaper

**User data**

	<b>Suitability</b>	<b>V<sub>c</sub></b>	<b>ISO code</b>
Alu Mg	suitable only under restricted conditions		
Steel < 900 N/mm <sup>2</sup>	suitable only under restricted conditions		
Steel < 1400 N/mm <sup>2</sup>	suitable only under restricted conditions		
Steel < 55 HRC	suitable only under restricted conditions		
CuZn	suitable only under restricted conditions		
Plastic, GRP	suitable		
Wood	suitable		
Paint	suitable		
Uni	suitable		
wet maximum	suitable only under restricted conditions		
dry	suitable		