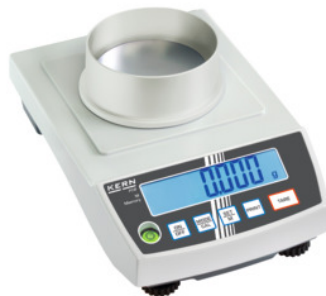


KERN**Precision scales, type PCB, maximum weighing range: 350g**

Order data

Order number	479510 350
GTIN	
Item class	47D

Description

Version:

- **Selectable mains and battery operation. Attention: German version! Please order a GB adapter plug No. 08 1174_GB separately. Auto-off after 3 minutes.**
- **CAL calibration programme: For accuracy adjustment (required external calibration weight available on request).**
- **Quantity counting: Reference quantities selectable 5, 10, 25, 50 pieces. Display selectable between pieces and weight.**
- **Formulation weighing: Separate memory for weight of the tare vessel and of the formulation ingredients (net totals).**

Supplied with:

Mains adapter 230 V/ 50 Hz and protective hood.

Optional extras:

Battery No. 081561 size 6LR61; internal rechargeable battery on request. Data cable, printer on request.

Technical description

Net weight	1.1 kg
Height	79 mm

Manufacturer's designation	PCB
Linearity	± 0.005 g
Settling time	3 s
Width	163 mm
Scale divisions	0.001 g
Reproducibility	0.002 g
maximum weighing range	0 - 350 g
Dimensions of weighing plate	Ø 81 mm
Minimum unit weight	0.02 g
Depth	245 mm
Power supply	Rechargeable battery-powered
Power supply	Battery-powered
Interface	RS232 interface
Calibration	K2
Type of product	Precision balance

Services

CalibrationScales maximum weighing range 50 kg	027700 50
DAkkS calibrationScales maximum weighing range 50	027710 50