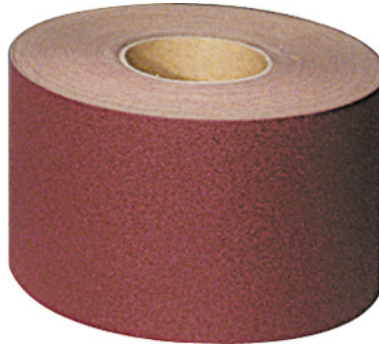


**Abrasive cloth (A) economy roll, brown KK 114 F, 115 mm × 50 m, Grit: 80****Order data**

Order number	557850 80
GTIN	4018875206133
Item class	56V

**Description****Version:**

Densely woven cotton cloth evenly spread with synthetic resin bonded **Aluminium Oxide (A)**. Very good grit bonding, high abrasion performance and long service life.

Type **VSM KK 114 F: Brown fabric, for extremely demanding applications**. This grade is **particularly supple, resistant to oil and petroleum** and can be torn in longitudinal direction to yield clean edges without fraying.

Packaging tape **without tear-off cutter**.

**Application:**

Predominantly for rubbing down metals by hand, but also suitable for all other materials. Ideal for use on orbital sanders.

**Technical description**

Grit designation	coarse
Grit	80
Grinding media	Standard aluminium oxide (A)
Grinding medium code	A
Economy roll width	115 mm

Economy roll length	50 m
Product name attribute	115 mm × 50 m
Type of product	Abrasive cloth

## User data

	Suitability	V <sub>c</sub>	ISO code
Alu Mg	suitable		
Steel < 900 N/mm <sup>2</sup>	suitable		
Steel < 1400 N/mm <sup>2</sup>	suitable		
Steel < 55 HRC	suitable		
Steel < 60 HRC	suitable only under restricted conditions		
Steel < 67 HRC	suitable only under restricted conditions		
INOX	suitable		
Ti	suitable only under restricted conditions		
GG(G)	suitable		
CuZn	suitable		
Plastic, GRP	suitable		
Wood	suitable		
Paint	suitable only under restricted conditions		
Uni	suitable		
dry	suitable		