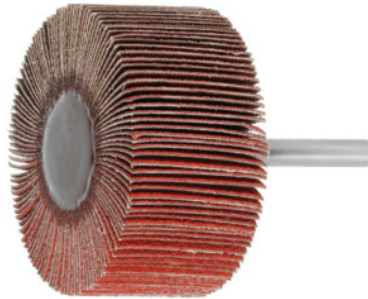


Garant**Flap wheel (CER), 120 grit, Head \varnothing ×head width: 40X15mm****Order data**

| | |
|--------------|---------------|
| Order number | 554170 40X15 |
| GTIN | 4045197882837 |
| Item class | 51E |

Description**Version:**

Flap strips bonded on to the shank of the tool.
Abrasive strips covered with **ceramic grit (CER)**.

Application:

Primarily for finish grinding and polishing tasks on larger radii in tool and mould making, for vessel and machine fabrication. The abrasive strips adapt to the contours of the component.

Technical description

| | |
|---------------------|-------------------------|
| recommended speed | 12000 min ⁻¹ |
| maximum speed | 19100 min ⁻¹ |
| Grit | 120 |
| Head width | 15 mm |
| Shank \varnothing | 6 mm |
| Head \varnothing | 40 mm |
| Grinding media | Ceramic grit (CER) |

| | |
|------------------------|------------|
| Grinding medium code | Ceramic |
| Product name attribute | 120 grit |
| Type of product | Flap wheel |

User data

| | Suitability | V _c | ISO code |
|--------------------------------|---|----------------|----------|
| Steel < 900 N/mm ² | suitable only under restricted conditions | | |
| Steel < 1400 N/mm ² | suitable | | |
| Steel < 55 HRC | suitable | | |
| Steel < 60 HRC | suitable | | |
| Steel < 67 HRC | suitable | | |
| INOX | suitable | | |
| Ti | suitable | | |
| GG(G) | suitable | | |
| CuZn | suitable | | |
| Plastic, GRP | suitable | | |
| Wood | suitable | | |
| dry | suitable | | |