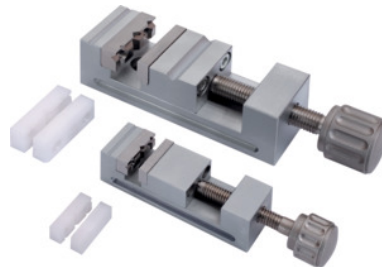


**Precision vice, Jaw width A: 15mm****Order data**

Order number	494480 15
GTIN	4045197525406
Item class	42L

Description**Version:**

Precision vice in hard chrome-plated (brass) or anodised (aluminium) version. Ideal for use with small parts, e.g. on microscopes and shadowgraphs or with surface roughness measuring tools. Angular accuracy 0.04 mm, exchangeable clamping jaws of hardened, stainless steel and plastic. Fixed jaws with Vees for cylindrical parts. The additional Vee on the fixed jaw and the clamping slots on the long sides increase the versatility.

Technical description

Material of vice	hard chrome-plated brass
Overall height c	15 mm
Overall length a	50 mm
maximum clamping range b	14.5 mm
Jaw width A	15 mm
Jaw height C	6 mm
Overall width B	15 mm
Type of product	Checking vice

