


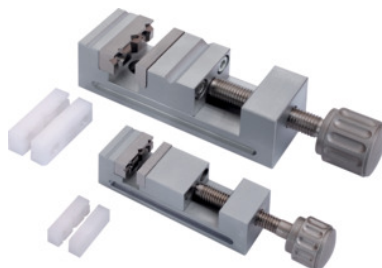

Precision vice, Jaw width A: 25mm



Order data

Order number	494480 25
GTIN	4045197525413
Item class	42L

Description

Version:

Precision vice in hard chrome-plated (brass) or anodised (aluminium) version. Ideal for use with small parts, e.g. on microscopes and shadowgraphs or with surface roughness measuring tools. Angular accuracy 0.04 mm, exchangeable clamping jaws of hardened, stainless steel and plastic. Fixed jaws with Vees for cylindrical parts. The additional Vee on the fixed jaw and the clamping slots on the long sides increase the versatility.

Technical description

Material of vice	Aluminium anodised
Overall height c	25 mm
maximum clamping range b	24.5 mm
Overall length a	75 mm
Jaw width A	25 mm
Jaw height C	10 mm
Overall width B	25 mm
Type of product	Checking vice

