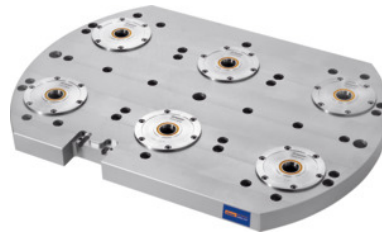


Garant
**ZeroClamp base plate (depending on the machine type / machine table),
Type: 29607**

Order data

Order number	360014 29607
GTIN	4045197885104
Item class	310

Description
Version:

Centre bore \varnothing 25 H7 to take the centring set.

Material:

Base plate of high-tensile aluminium, surface treated.

All components of the clamping pot of stainless or corrosion-resistant steel.

Optional extras:

Clamping stud No. 360025, connection blocks No. 360017 size 12808 / 12805.

Note:

Depending on the machine type, the arrangement may differ from that in the illustration.

suitable for machine type: Hermle C12 / 22 / 250

Clamping pot \varnothing : 120 mm

Number of clamping pots: 4

\varnothing A: 330 mm

Height H: 44 mm

Pitch S: 200 mm

Technical description

suitable for machine type	Hermle C12 / 22 / 250
Pitch S	200 mm

Clamping pot Ø	120 mm
Type	29607
Number of clamping pots	4
Ø A	330 mm
Height H	44 mm
Dimension across diagonals	yes
Series	ZeroClamp
Type of product	Zero-point clamping system

Accessories

ZeroClamp cover plate for base plate Type 29611	360021 29611
ZeroClamp clamping stud with internal thread Type 18M16/190	360025 18M16/190
ZeroClamp clamping stud with internal thread Type 18M12/138	360025 18M12/138
ZeroClamp clamping stud with internal thread Type 12M10/190	360025 12M10/190
ZeroClamp clamping stud with internal thread Type 14M12/90	360025 14M12/90
ZeroClamp clamping stud with internal thread Type 30M24/190	360025 30M24/190
ZeroClamp clamping stud with internal thread Type 16M10	360025 16M10
ZeroClamp clamping stud with internal thread Type 12M10	360025 12M10
ZeroClamp clamping stud with internal thread Type 18M16	360025 18M16
ZeroClamp clamping stud with internal thread Type 25M16/138	360025 25M16/138
ZeroClamp clamping stud with internal thread Type 18M16/138	360025 18M16/138

ZeroClamp clamping stud with internal thread Type 16M8	360025 16M8
ZeroClamp clamping stud with internal thread Type 25M10/138	360025 25M10/138
ZeroClamp clamping stud with internal thread Type 12M10/138	360025 12M10/138
ZeroClamp clamping stud with internal thread Type 25M10	360025 25M10
ZeroClamp clamping stud with internal thread Type 12M10/90	360025 12M10/90
ZeroClamp connection block Type 12808	360017 12808
ZeroClamp connection block Type 12805	360017 12805
ZeroClamp clamping stud with internal thread Type 18M12	360025 18M12