




## Velour-backed abrasive disc ABRANET®, Ø 150 mm, Grit: 400

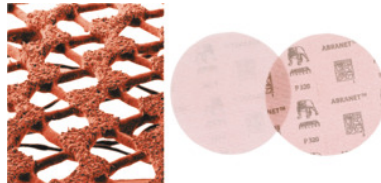

### Order data

Order number	567800 400
GTIN	6416868646368
Item class	56M

### Description

#### Version:

Velour-backed abrasive discs consisting of a **mesh structure** of polyamide fabric containing thousands of holes and coated with abrasive grit.

#### Advantage:

- **Dust-free grinding: very low impact on workplace and environment.**
- **No clogging of the grinding wheel (surface defects and dust balls are avoided).**
- **Guaranteed improved surface finishes with less grinding media consumption.**
- **High effectiveness – the removal rate increases by several orders of magnitude depending on the surface.**

#### Application:

Grinding of paints, fillers primers, (fibre-reinforced) plastics, non-ferrous metals and aluminium alloys, furniture components.

### Technical description

Grit	400
Disc Ø	150 mm
Series	ABRANET®
Grinding medium code	A
Iron, sulphur and chlorine constituents	< 0.1 %
Product name attribute	Ø 150 mm

Propulsive equipment	Orbital sander
maximum circumferential speed	40 m/s
Type of product	Velour-backed abrasive disc

## User data

	Suitability	V <sub>c</sub>	ISO code
Alu Mg	suitable		
Steel < 900 N/mm <sup>2</sup>	suitable only under restricted conditions		
CuZn	suitable		
Plastic, GRP	suitable		
Wood	suitable		
Paint	suitable		
dry	suitable		

## Accessories

PU hook and loop backing pad External Ø 150 mm	567885 150
Multi-hole PU backing pad External Ø 147 mm	567990 147
PU hook and loop backing pad Multiple holes Outer Ø 150 mm	567887 150