


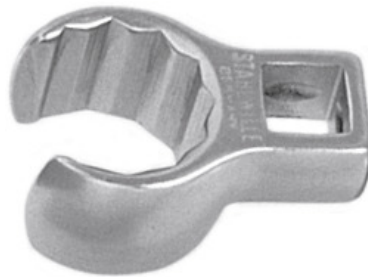

Crowfoot wrench Open ring form, Width across flats: 21 mm



Order data

Order number	612920 21
GTIN	4018754003426
Item class	63A

Description

Version:

Drop forged, head with square socket for drive tools such as ratchet, extension etc.

Application:

The possibility of accepting various different drive tools means that access to restricted places is made easier.

Material:

Chrome alloy steel, chrome-plated, round finish surface (no sharp edges).

Note:

For suitable drive tools see No. 632000 – 641350 and 655230 – 657766.

Technical description

Square drive	3/8 in
Width across flats	21 mm
Head thickness h	18.5 mm
Head width b	31.3 mm
Length L	42.8 mm
Form, output drive	Open ring form
Material	Chrome alloy steel

Surface	chrome-plated
Type of product	Socket insert

Accessories

Extension, 3/8 inch overall length 160 mm	635400 160
Extension, 3/8 inch QuickRelease overall length 75 mm	635645 75
Extension, 3/8 inch QuickRelease overall length 160 mm	635645 160
Extension, 3/8 inch overall length 75 mm	635429 75
Extension, 3/8 inch overall length 125 mm	635420 125
Universal joint, 3/8 inch Type 3/8	636220 3/8
Extension, 3/8 inch overall length 125 mm	635429 125
Push-through ratchet, 3/8 inch with short handle	635900
Extension, 3/8 inch overall length 40 mm	635400 40
Extension, 3/8 inch flexible overall length 194 mm	635600 194
Reversible precision ratchet 3/8 inch with ejector and twist handle	635220
Precision ratchet "Zyklop Speed" reversible, 3/8 inch with swivel head and ejector	635190
Universal joint, 3/8 inch Type 3/8	636229 3/8
Extension, 3/8 inch overall length 75 mm	635420 75
Universal joint, 3/8 inch QuickRelease Type 3/8	636250 3/8
Special extension 3/8 inch	612950
Reversible ratchet, 3/8 inch with ejector Type 3/8	635090 3/8
Extension, 3/8 inch QuickRelease overall length 240 mm	635645 240
Extension, 3/8 inch overall length 40 mm	635420 40
T-handle, 3/8 inch QuickRelease overall length 165 mm	635750 165
Extension, 3/8 inch overall length 75 mm	635400 75
Extension, 3/8 inch overall length 240 mm	635429 240

Swivel handle, 3/8 inch	636000
Precision ratchet "Zyklop Metal" reversible, 3/8 inch with ejector	635295
T-handle, 3/8 inch overall length 200 mm	635729 200
Extension, 3/8 inch overall length 240 mm	635400 240
T-handle, 3/8 inch overall length 200 mm	635720 200
T-handle, 3/8 inch overall length 165 mm	635700 165
Flexi-head ratchet, 3/8 inch with ejector	635335
Universal joint, 3/8 inch Type 3/8	636200 3/8
Reversible ratchet, 3/8 inch with ejector Type	635025
Precision ratchet "Zyklop Metal" push-through square drive, 3/8 inch with ejector	635290
Extension, 3/8 inch overall length 125 mm	635400 125