


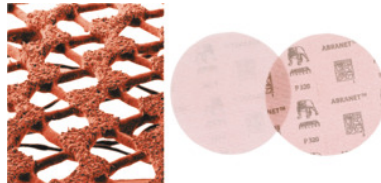

Velour-backed abrasive disc ABRANET®, Ø 77 mm, Grit: 120



Order data

| | |
|--------------|---------------|
| Order number | 567801 120 |
| GTIN | 6416868666519 |
| Item class | 56M |

Description

Version:

Velour-backed abrasive discs consisting of a **mesh structure** of polyamide fabric containing thousands of holes and coated with abrasive grit.

Advantage:

- **Dust-free grinding: very low impact on workplace and environment.**
- **No clogging of the grinding wheel (surface defects and dust balls are avoided).**
- **Guaranteed improved surface finishes with less grinding media consumption.**
- **High effectiveness – the removal rate increases by several orders of magnitude depending on the surface.**

Application:

Grinding of paints, fillers primers, (fibre-reinforced) plastics, non-ferrous metals and aluminium alloys, furniture components.

Technical description

| | |
|---|----------|
| Grit | 120 |
| Disc Ø | 77 mm |
| Series | ABRANET® |
| Grinding medium code | A |
| Iron, sulphur and chlorine constituents | < 0.1 % |
| Product name attribute | Ø 77 mm |

| | |
|-------------------------------|-----------------------------|
| Propulsive equipment | Orbital sander |
| maximum circumferential speed | 40 m/s |
| Type of product | Velour-backed abrasive disc |

User data

| | Suitability | V _c | ISO code |
|-------------------------------|---|----------------|----------|
| Alu Mg | suitable | | |
| Steel < 900 N/mm ² | suitable only under restricted conditions | | |
| CuZn | suitable | | |
| Plastic, GRP | suitable | | |
| Wood | suitable | | |
| Paint | suitable | | |
| dry | suitable | | |

Accessories

| | |
|---|-----------|
| PU hook and loop backing pad External Ø 77 mm | 567885 77 |
|---|-----------|