


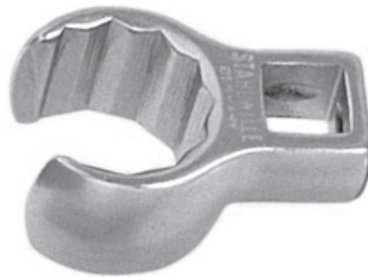

## Crowfoot wrench Open ring form, Width across flats: 27mm



### Order data

Order number	612920 27
GTIN	4018754003464
Item class	63A

### Description

**Version:**

Drop forged, head with square socket for drive tools such as ratchet, extension etc.

**Application:**

The possibility of accepting various different drive tools means that access to restricted places is made easier.

**Material:**

Chrome alloy steel, chrome-plated, round finish surface (no sharp edges).

**Note:**

For suitable drive tools see No. 632000 – 641350 and 655230 – 657766.

### Technical description

Width across flats	27 mm
Square drive	3/8 in
Head thickness h	21.4 mm
Head width b	40 mm
Length L	52.8 mm
Form, output drive	Open ring form
Material	Chrome alloy steel

Surface	chrome-plated
Type of product	Socket insert

## Accessories

Universal joint, 3/8 inch Type 3/8	636220 3/8
Extension, 3/8 inch overall length 75 mm	635400 75
Extension, 3/8 inch overall length 75 mm	635429 75
Extension, 3/8 inch overall length 125 mm	635429 125
Reversible ratchet, 3/8 inch with ejector Type	635025
Extension, 3/8 inch overall length 240 mm	635400 240
Reversible precision ratchet 3/8 inch with ejector and twist handle	635220
Reversible ratchet, 3/8 inch with ejector Type 3/8	635090 3/8
Universal joint, 3/8 inch Type 3/8	636200 3/8
Extension, 3/8 inch overall length 40 mm	635400 40
Extension, 3/8 inch QuickRelease overall length 160 mm	635645 160
Extension, 3/8 inch QuickRelease overall length 240 mm	635645 240
Extension, 3/8 inch overall length 160 mm	635400 160
Extension, 3/8 inch overall length 40 mm	635420 40
Special extension 3/8 inch	612950
Extension, 3/8 inch overall length 240 mm	635429 240
Precision ratchet "Zyklop Speed" reversible, 3/8 inch with swivel head and ejector	635190
Precision ratchet "Zyklop Metal" reversible, 3/8 inch with ejector	635295
Extension, 3/8 inch overall length 125 mm	635400 125
Extension, 3/8 inch overall length 125 mm	635420 125
T-handle, 3/8 inch overall length 200 mm	635720 200
T-handle, 3/8 inch overall length 165 mm	635700 165

Extension, 3/8 inch flexible overall length 194 mm	635600 194
Universal joint, 3/8 inch Type 3/8	636229 3/8
T-handle, 3/8 inch QuickRelease overall length 165 mm	635750 165
Extension, 3/8 inch overall length 75 mm	635420 75
Push-through ratchet, 3/8 inch with short handle	635900
Swivel handle, 3/8 inch	636000
Precision ratchet "Zyklop Metal" push-through square drive, 3/8 inch with ejector	635290
Flexi-head ratchet, 3/8 inch with ejector	635335
Universal joint, 3/8 inch QuickRelease Type 3/8	636250 3/8
Extension, 3/8 inch QuickRelease overall length 75 mm	635645 75
T-handle, 3/8 inch overall length 200 mm	635729 200