




## Universal joint socket, 3/8 inch, Width across flats: 16mm

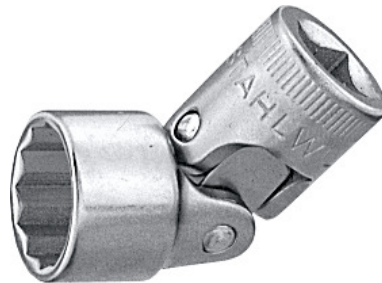

### Order data

|              |               |
|--------------|---------------|
| Order number | 637400 16     |
| GTIN         | 4018754002528 |
| Item class   | 63A           |

### Description

**Version:**

Forged from high quality steel, internally bevelled for easy fitting to bolt heads. Internal square to **DIN 3120**.

Optimum grain orientation due to special forging process. Close tolerance sockets with **AS drive** profile protect corners of bolt head. Hardened in an oil bath, stress-relieved and distortion-free for a precision fit. Smoothed finish.

**Standard:**

**DIN 3124 L**

**Material:**

HPQ® high performance steel, non-flaking chrome-plated over nickel.

### Technical description

|                    |               |
|--------------------|---------------|
| Ø drive output end | 21.8 mm       |
| Width across flats | 16 mm         |
| Length             | 51.5 mm       |
| Square drive       | 3/8 in        |
| Drive profile      | Bi-hex socket |
| Type of product    | Socket insert |

