


LESSMANN®
THE GERMAN BRUSH COMPANY

Dished bevel brush Right-left knotted, stainless steel wire 0.50 mm, Brush Ø D1× thread M: 115XM14mm

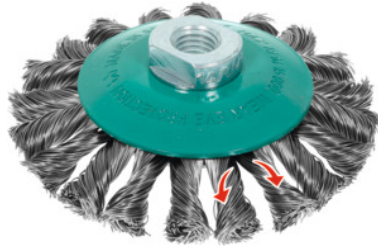

Order data

Order number	571355 115XM14
GTIN	4017359380154
Item class	57L

Description

Version:

Dished **bevel brush** with smooth wire 0.50 mm, **knotted** and firmly crimped into the steel body. **Very aggressive brushing effect with high wear resistance.**

Application:

Right-left knotted for increased aggressiveness for heavy-duty brushing work. Very suitable for use at corners and edges, with a smooth action.

Ideal for working where access is difficult and for heavy brush work, e.g. descaling, removing rust, removing paint, roughening, cleaning metal parts, also for cleaning formwork boards.

With **internal thread M14**, for direct mounting **on angle grinders**.

Technical description

Number of twisted knots	20
Bristle thickness	0.5 mm
Brush Ø D ₁	115 mm
maximum speed	12500 min ⁻¹
Length of brush section H ₁	24 mm
Bristle width L ₁	12 mm

Thread M	M14
Brush material	Stainless steel wire
Twisted knotting	Right-left knotted
Type of product	Bevel brush