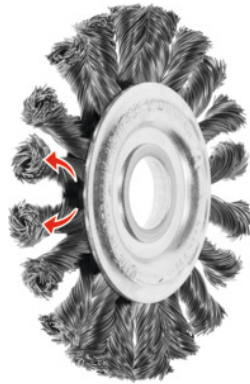


LESSMANN®
THE GERMAN BRUSH COMPANY**Wheel brush Right-left knotted, steel wire 0.50 mm, Brush Ø D1× bore Ø d1 / thread M: 115X22mm**

Order data

Order number	571205 115X22
GTIN	4017359385838
Item class	57L

Description

Version:

Straight round brush with smooth wire 0.50 mm, **knotted** and firmly crimped into the steel body. **Very aggressive brushing effect with high wear resistance.**

Application:

Right-left knotted for increased aggressiveness for heavy-duty brushing work. Very suitable for use at corners and edges, with a smooth action.

For heavy brush work, e.g. descaling, removing rust, removing paint, roughening, cleaning metal parts, also for cleaning formwork boards.

Technical description

Brush Ø D ₁	115 mm
Bristle thickness	0.5 mm
Length of brush section H ₁	24 mm
Number of twisted knots	20

maximum speed	12500 min ⁻¹
Bristle width L ₁	14 mm
Bore Ø d ₁	22 mm
Brush material	Steel wire
Type of product	Wheel brush