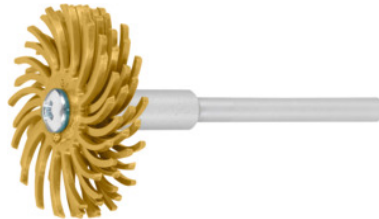


3M Scotch-Brite™

Bristle-Brush type C Ø 25 mm Set 24 pieces, shank Ø 3 mm., RB-ZB, Grit: 80**Order data**

Order number	573545 80
GTIN	30048011276121
Item class	53M

Description**Version:**

Cast special cleaning brushes are homogeneous grinding bodies with a mixture of precision-formed ceramic grit and Aluminium Oxide, and an **exceptionally long working life. Extremely flexible and versatile.**

The **radial** bristle brush consists of individual segments (approx. 1.6 mm wide).

Removable mandrel (**shank Ø 3 mm**). Segments can be combined to make up any desired brush width.

With curved bristles (type C) for use on **profiled surfaces**.

Application:

Ensure the correct direction of rotation.

Requires no accessories for use on straight grinders or flexible shafts.

On virtually all materials, with the highest possible safety. Removal of rust, remains of adhesive, paint, light scratches and burrs. For smoothing, finishing, polishing, cleaning, and deburring.

Supplied with:

24 individual segments (approx. 1.6 mm wide) **including mandrel** with shank Ø 3 mm.

Technical description

Colour	yellow
Grit	80
Brush Ø D ₁	25 mm

maximum speed	35000 min ⁻¹
Brush width	1.6 - 10 mm
Shank Ø D _s	3 mm
Grinding medium code	Ceramic
Product name attribute	RB-ZB
Manufacturer's designation	RB-ZB
Type of product	Wheel brush