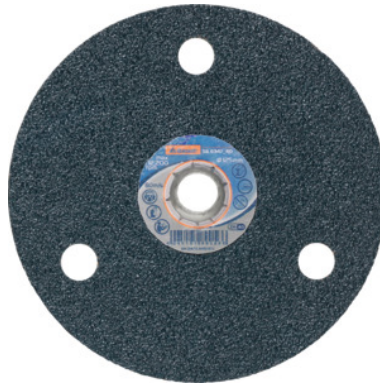


Garant**Double-sided grinding disc (ZA) Thread M14, Ø 125 mm, Grit: 60****Order data**

Order number	566347 60
GTIN	4045197890306
Item class	51M

Description**Version:**

Innovative grinding disc with **double-sided abrasive grit coating** Zirconium Aluminium Oxide (ZA) and **extremely thin, sturdy design** (3.5mm). More control for precise working thanks to **viewing holes**. With M14 thread for direct mounting on angle grinders, for use with adapter No. 566348.

Application:

Versatile application options, **precise chamfering** with low approach angle, **double-sided grinding in tight spaces** in a single operation, plunging into grooves.

Technical description

Disc Ø	125 mm
Grit	60
Shape description	straight
Grinding media	Zirconium aluminium oxide (ZA)
Grinding medium code	ZA

Iron, sulphur and chlorine constituents	< 0.1 %
Product name attribute	Ø 125 mm
Thread	M14
recommended approach angle	3-5 degrees
optimised for material	Steel
optimised for material	INOX
maximum circumferential speed	80 m/s
Type of product	Grinding disc double-sided

Accessories

M14 clamping flange for double-sided grinding disc	566348
--	--------