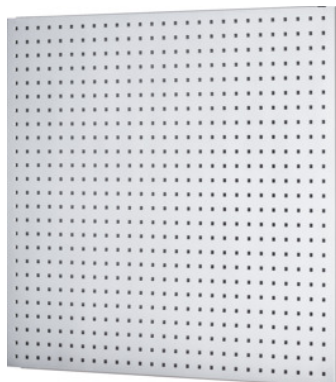


Garant GRIDLINE

Perforated panel double-sided for ToolTruck, Usable height: 950mm**Order data**

Order number	914856 950
GTIN	4045197894045
Item class	9GT

Description**Version:**

Pair of support columns of 25×25 mm steel hollow section with sheet metal perforated panel (□ 9×9 mm on a 37-mm grid), silver powder-coated.

Perforated panel with grid.

Suitable for:

No. 914560, 914564, 914568.

Supplied with:

Sheet metal perforated panel with a pair of support columns.

Technical description

Perforated panel width	1025 mm
Perforated panel height	950 mm
Height	950 mm
Series	ToolTruck
Application range	Mobile workbench
Hoffmann perforated panel grid interval	9×9 mm

Type of product

Perforated rear panel

Accessories

LED lamp for ToolTruckwithout support columns Type 20

914872 20