




## Diamond cup grinding wheel D×T×H (mm), 100×35×20, Type: D64

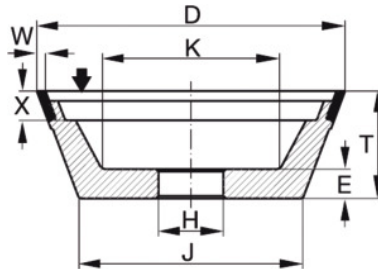

### Order data

Order number	597520 D64
GTIN	9003176752729
Item class	53Y

### Description

#### Version:

**Cup grinding wheels and dished grinding wheels with diamond abrasive coating.** Fine-grained for the best surface quality and good metal removal rates. **Specification: D64C50B DIAGO W-Carbide.**

#### Application:

**For general use on all common tool grinding machines.** For grinding **carbide tools and short chipping non-ferrous materials.** Very well suited to dry grinding, but can also be used for wet grinding.

### Technical description

Grit	D64
Grinding medium code	D
Specification	D64C50B DIAGO W-Carbide
Grinding media	Diamond
Grinding process	Tool grinding
Shape	11V9
Disc Ø D	100 mm

Disc thickness T	35 mm
Product name attribute	100×35×20
Bore Ø H	20 mm
Abrasive coating width W end face	2 mm
Abrasive coating height X	10 mm
Type of product	Tapered cup grinding wheel

### User data

	Suitability	V <sub>c</sub>	ISO code
Carbide (HM)	suitable		
Plastic, GRP	suitable only under restricted conditions		
wet maximum	suitable only under restricted conditions		
dry	suitable		