




Diamond dished grinding wheel D×T×H (mm), 100×10×20, Type: D126

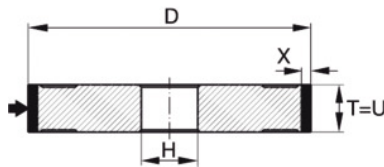

Order data

Order number	597910 D126
GTIN	9003176128609
Item class	53Y

Description

Version:

Cup grinding wheels and dished grinding wheels with diamond abrasive coating.

General-purpose grit for medium to fine surface quality and very good metal removal rates.

Specification: D126C75B DIAGO W-Carbide.

Application:

For general use on all common tool grinding machines. For grinding **carbide tools and short chipping non-ferrous materials.** Very well suited to dry grinding, but can also be used for wet grinding.

Shape: 1A1

Abrasive coating height X: 3 mm

Grinding medium code: D

Technical description

Grit	D126
Specification	D126C75B DIAGO W-Carbide
Grinding medium code	D
Grinding process	Tool grinding
Grinding media	Diamond
Shape	1A1
Disc Ø D	100 mm

Disc thickness T	10 mm
Product name attribute	100×10×20
Bore Ø H	20 mm
Abrasive coating width W end face	10 mm
Abrasive coating height X	3 mm
Type of product	Sanding pad

User data

	Suitability	V _c	ISO code
Carbide (HM)	suitable		
Plastic, GRP	suitable only under restricted conditions		
wet maximum	suitable only under restricted conditions		
dry	suitable		