


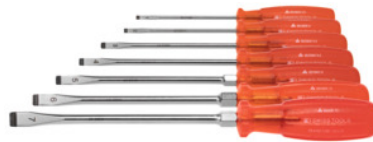

Screwdriver set for slot-head, with "multicraft" power grip, Number of screwdrivers: 7



Order data

Order number	660910 7
GTIN	7610733085705
Item class	63E

Description

Version:

Versatile, robust screwdriver with taper blade (tip) and hexagon flats for wrench assistance. **"Multicraft" power grip** of impact resistant plastic (cadmium free), particularly easy grip, even with oily hands.

Blade of PB Swiss Tools special alloy combines maximum hardness with exceptional toughness. With parallel stepped tip. From size 8 with hexagon flats for wrench assistance. Surface nickel-plated and chrome-plated, black tip.

Advantage:

- **Stepped plane parallel tips provide full-surface instead of linear contact, enabling higher torque transmission.**
- **No cam-out effect.**
- **Tips perfectly fit standard and non-standard screw slot sizes.**
- **Smooth, burr-free rounding of the end of the handle prevents friction in the palm of the hand.**
- **Rounded ergonomic shape with comfortable easy-grip surface ensures non-fatiguing working and high torque transmission.**
- **Non-roll flats.**
- **Marked with drive symbol and size.**

Application:

For repair and assembly work, for loosening tight screws etc.

Content:

1 each screwdriver No. 660900: Size 3.5; 4; 5.5; 6.5; 8; 10; 13

Technical description

Number of screwdrivers	7
Drive profile	Slot-head screwdriver
Type of product	Screwdriver

Accessories

Screwdriver for slot-head, with "multicraft" power grip Blade width b 6,5 mm	660900 6,5
Screwdriver for slot-head, with "multicraft" power grip Blade width b 10 mm	660900 10
Screwdriver for slot-head, with "multicraft" power grip Blade width b 13 mm	660900 13
Screwdriver for slot-head, with "multicraft" power grip Blade width b 3,5 mm	660900 3,5
Screwdriver for slot-head, with "multicraft" power grip Blade width b 5,5 mm	660900 5,5
Screwdriver for slot-head, with "multicraft" power grip Blade width b 4 mm	660900 4
Screw holder Type 1	666425 1
Screwdriver for slot-head, with "multicraft" power grip Blade width b 8 mm	660900 8