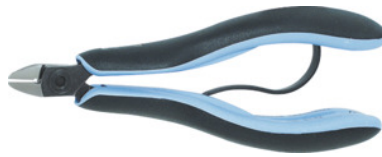


LINDSTRÖM

Electronics side cutter, small head, kW, overall length: 135mm**Order data**

Order number	726040 135
GTIN	7314150103058
Item class	73M

Description**Version:**

Slim style with precision ground induction hardened jaw edges (63 - 65 HRC). Black surface to reduce reflections. Adjustable precision screw joint for minimal friction and optimum axial alignment of the cutters. **Suitable for ESDs**, with ergonomic **2-component** grips. The patented opening spring reduces the resistance when closing the cutter. Thus the force is concentrated on the cut.

Material:

High-performance ball-bearing steel, drop forged, burnished.

Technical description

overall length	135 mm
Head width	10.5 mm
Cutting capacity copper wire up to Ø	0.1 - 1 mm
Cutter length	10 mm
electrostatic characteristic	EGB/ESD
Cutting chamfer	without bevel
Material	High-performance ball-bearing steel
Head shape	narrow
Handle	2-component grip

Manufacturing process	Cutting edges induction hardened (63 – 65 HRC)
Surface	black burnished
Product name attribute	kW
with return spring	yes
adjustable precision screw joint	yes
Type of product	Cutting pliers