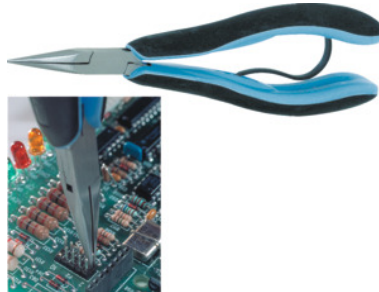


LINDSTRÖM

Electronics snipe-nosed pliers, serrated jaws, overall length: 150mm**Order data**

Order number	726160 150
GTIN	7314150103225
Item class	73M

Description**Version:**

Slim shape with narrow jaws. Jaws with rounded outer edges. Precision box joint with extra long slides for maximum stability with minimum friction. Mirror-polished head and joint. **Suitable for ESDs**, with ergonomic **2-component** grips. The patented opening spring reduces the resistance when closing the pliers, therefore the force applied to the component can be accurately gauged. Long snipe nose, serrated internal jaws.

Material:

High-performance ball-bearing steel, drop forged.

Technical description

Head width	9 mm
overall length	150 mm
Jaw length	32 mm
electrostatic characteristic	EGB/ESD
Jaw design	Snipe nose, serrated internal jaws
Type of jaws	inside smooth
Handle	2-component grip

Manufacturing process	Cutting edges induction hardened (45 – 48 HRC)
Material	High-performance ball-bearing steel
Surface	mirror polished
with return spring	yes
Type of product	Snipe nose pliers