


Sheet steel toolbox "Robust", Type: 5/530

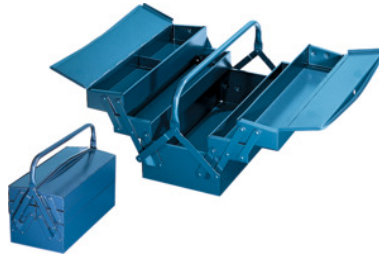

Order data

Order number	693465 5/530
GTIN	2050001021779
Item class	66K

Description

Version:

Lockable with padlock (No. 085830 ff). Upper parts attached with continuous hinge strip.

Especially strong construction, in part of **0.9 mm sheet steel**.

Colour:

Tool box paint finish blue, powder-coated all round.

Technical description

External dimension width	200 mm
External dimension length	530 mm
Version	5-part
External dimension height	200 mm
Weight	6.3 kg
Type of product	Tool transport system

Accessories

Precision cylinder lockshared keys Body Ø 50 mm	085870 50
Combination padlock with high shackle Body Ø 50 mm	085832 50
Combination padlock Body Ø 40 mm	085830 40
Precision cylinder lock with high shackleshared keys Body Ø 40 mm	085876 40
Precision cylinder lock with high shackleindividual keys Body Ø 40 mm	085875 40
Combination padlock Body Ø 40 mm	085885 40
Cylinder padlock with high shackleindividual keys Body Ø 40 mm	085882 40
Cylinder padlockindividual keys Body Ø 50 mm	085880 50
Precision cylinder lockindividual keys Body Ø 40 mm	085855 40
ALUTITAN padlockindividual keys Body Ø 50 mm	085868 50
Combination padlock Body Ø 50 mm	085831 50
Precision cylinder lockindividual keys Body Ø 50 mm	085850 50
Cylinder padlock standard qualityindividual keys Body Ø 50 mm	085860 50
Cylinder padlock set4 pieces per set, shared keys Body Ø 40 mm	085865 40
Cylinder padlock with high shackleindividual keys Body Ø 40 mm	085866 40
Cylinder padlockindividual keys Body Ø 50 mm	085890 50