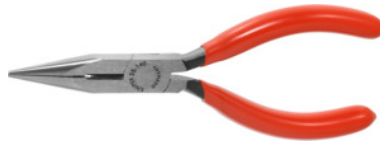


**Snipe nose pliers, straight, polished, overall length: 140mm****Order data**

Order number	713150 140
GTIN	4003773033158
Item class	73F

**Description****Version:**

Very long snipe nose jaws. Cutting edges induction hardened (approx. 61 HRC), suitable for hard and soft wire. Serrated inside jaws.

Jaws chemically blackened, head bright polished. Plastic coated handles. Twist-tolerant flexible precision tips.

**Standard:**

**DIN ISO 5745**

**Material:**

Chrome vanadium steel, drop-forged and oil-hardened.

**Technical description**

overall length	140 mm
Jaw length	42 mm
Handle	Multi-component covering
Jaw design	snipe-nosed, straight
Standard	DIN ISO 5745
Jaw characteristics	Cutting edges induction hardened (approx. 60 HRC)
Type of jaws	inner face roughened
Material	Chromium vanadium steel

Surface	chemically blackened, head bright polished
Type of product	Multi-function pliers