


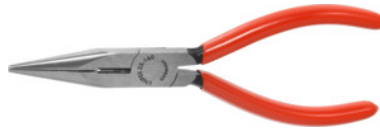

Snipe nose pliers, straight, polished, overall length: 160mm



Order data

Order number	713150 160
GTIN	4003773013099
Item class	73F

Description

Version:

Very long snipe nose jaws. Cutting edges induction hardened (approx. 61 HRC), suitable for hard and soft wire. Serrated inside jaws.

Jaws chemically blackened, head bright polished. Plastic coated handles. Twist-tolerant flexible precision tips.

Standard:

DIN ISO 5745

Material:

Chrome vanadium steel, drop-forged and oil-hardened.

Technical description

overall length	160 mm
Jaw length	50 mm
Handle	Multi-component covering
Jaw design	snipe-nosed, straight
Standard	DIN ISO 5745
Jaw characteristics	Cutting edges induction hardened (approx. 60 HRC)
Type of jaws	inner face roughened
Material	Chromium vanadium steel

Surface	chemically blackened, head bright polished
Type of product	Multi-function pliers