


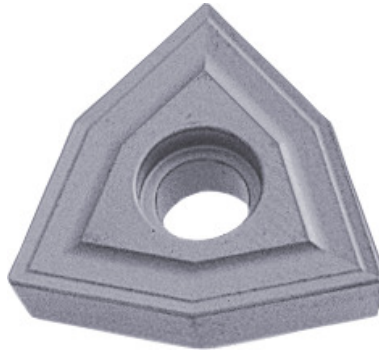

## KOMET® Unisix® indexable insert, BK7935, Designation type W29: 10-010



### Order data

Order number	236910 10-010
GTIN	4047109286252
Item class	24T

### Description

#### Suitable for :

No. 236630; 236635; 236650

#### Note:

The standard application values refer to the KUB Trigon®.

Type: INOX

ISO code indexable insert: WOEX 030204

Feed f in steel < 900 N/mm<sup>2</sup>: 0.08 mm/rev.

### Technical description

ISO code indexable insert	WOEX 030204
Designation	10-010
Feed f in steel < 900 N/mm <sup>2</sup>	0.08 mm/rev.
Number of changes/inserts	3
Grade	BK7935
Type	INOX
Tool material	Carbide

Type of product

Indexable insert for drilling

**User data**

	<b>Suitability</b>	<b>V<sub>c</sub></b>	<b>ISO code</b>
INOX < 900 N/mm <sup>2</sup>	suitable	160 m/min	M
wet maximum	suitable		
dry	suitable only under restricted conditions		