


## Garant

**Side lock arbor Nickel-plated, with cooling channel bore, HSK-A 100 short, Clamping  $\varnothing$  D1: 6mm**

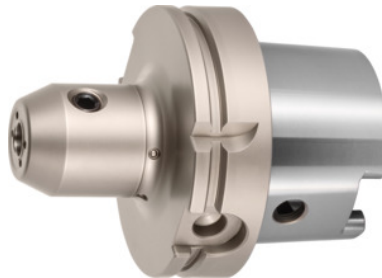

### Order data

Order number	304392 6
GTIN	4045197945617
Item class	31A

### Description

#### Version:

- With RFID/Balluffchip bore.
- HSK mating faces machined.

**GARANT:** All shanks hard turned (for smooth running!).

Special nickel plating.

**With coolant supply holes that can be plugged.**

#### Application:

For clamping tools with Weldon shank to DIN 1835 Form B and DIN 6535 Form HB.

#### Optional extras:

Coolant pipe No. 309880, coolant pipe wrench No. 309890

#### Note:

HSK 40 and 50, Form A and E available ex works by the manufacturer.

### Technical description

Clamping $\varnothing$ D <sub>1</sub>	6 mm
Overhang dimension A	80 mm
External $\varnothing$ D	25 mm
Spare clamping screw No. 30 9900	6

Adapter	HSK-A 100 short
Arbor standard	ISO 12164-1
Arbor standard	DIN 69882-4
Arbor standard	DIN 69893
Shape	A
Balance quality G at rotational speed	G 2.5 at 25,000 rpm
Concentricity	$\leq 3 \mu\text{m}$
Machining strategy	HSC
Machining strategy	HPC
Type of product	Side lock arbor

---

## Accessories

Spare clamping screw for chucks with clamping  $\varnothing$  D1 6 mm

309900 6